


192S2240

Measurement shunt 100mV 100mV 400A class 0,5

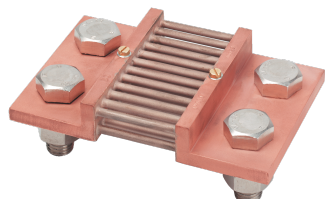

General characteristics

- 20 ratings from 1 to 4000 A, at 100 mV.
- Other ratings and secondary voltages available: please contact us.
- Voltage drop: 100 mV for nominal rating.
- Accuracy class: 0.5.
- Permanent overload: 1.2 In.
- 10 In/5s rating ? 500 A 5 In/5s rating 600 to 1500 A 2 In/5s rating ? 2500 A.

[Link to the reference](#)

Shunts provide indirect measurement of direct current by creating a standardised voltage drop.

----- System -----

Fill rate E-Order Common	33
Fill rate E-Order Selection	67

Classification

UNSPSC	39121032
ETIM Class	EC002303
IGCC	4186

Commerce

Effective date	1998-02-09
Country of origin	ES
Discount Policy	1EA10
Discount Policy Label	CURRENT TRANSFORMER

ETIM - Electrical characteristics

Primary current [A]	400
Secondary voltage [mV]	100

Logistics

GTIN/EAN	3596031089604
Customs number	9030900000
Price unit	PC
Weight of the packing unit	0.866
Length of the packing unit	0.19
Width of the packing unit	0.065
Depth of the packing unit	0.07

Technical Characteristics

Rated voltage	100 mV
Rated current	400

<https://apac.socomec.com/en/reference/192S2240>