


60620100

Cylindrical fuse with striker gG type 22x58 500Vac 100A

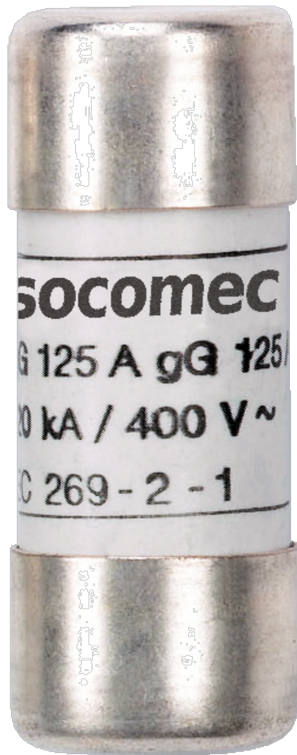

Industrial fuses protect installations and people from overcurrents for any low voltage electrical circuit.

Classification

UNSPSC	39121609
ETIM Class	EC002704
IGCC	4905

Commerce

Effective date	1988-04-15
Country of origin	ES
Discount Policy	1CF10
Discount Policy Label	CYLINDRICAL FUSE
Length of the product unit	0.051
Width of the product unit	0.0143
Weight	0.05

ETIM

Model	Ceramic fuse
Size	14x51 mm
Voltage type	AC
Rated current [A]	100
Rated voltage [V]	690
Rated operating frequency [Hz]	50..60
Type of fuse status indicator	Top fuse status indicator

Logistics

GTIN/EAN	3596031378609
Customs number	8536109090
Price unit	PC
Weight of the packing unit	0.05
Length of the packing unit	0.022
Width of the packing unit	0.022
Depth of the packing unit	0.058

Norms

Conformity to standards	IEC
-------------------------	-----

Technical Characteristics

Fuse melting indicator	with striker
Fuse size	22x58
Rated voltage	500 VAC
Rated current	100
Type	gG

Strong points

- High-performance
- Increased reliability
- Improved safety

General characteristics

- High-performance.
- High level of reliability.
- Improved safety.

Compliance with standards

- IEC 60269-1
- IEC 60269-2

Link to the reference



<https://apac.socomec.com/en/reference/60620100>